


**Parallel kit**  
**EAMM-U-50-S38-40P-78**  
Part number: 2155239

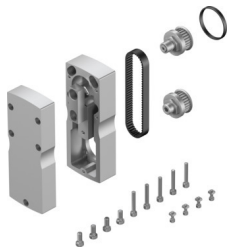

**Data sheet**

| Feature                               | Value                  |
|---------------------------------------|------------------------|
| Size                                  | 50                     |
| Mounting position                     | optional               |
| Gear unit ratio                       | 1:1                    |
| Max. rotational speed                 | 6000 rpm               |
| LABS (PWIS) conformity                | VDMA24364 zone III     |
| Storage temperature                   | -25 °C...60 °C         |
| Relative air humidity                 | 0 - 95%                |
| Degree of protection                  | IP40                   |
| Ambient temperature                   | -10 °C...60 °C         |
| Mass moment of inertia                | 12.1 kgmm <sup>2</sup> |
| Frictional torque independent of load | 0.01 Nm                |
| Transmittable torque                  | 1 Nm                   |
| Product weight                        | 577 g                  |
| Interface code, actuator              | S38                    |
| Interface code, motor in              | 40P                    |
| Note on materials                     | RoHS-compliant         |