


Axial kit EAMM-A-D40-67A-S1

Part number: 2256695

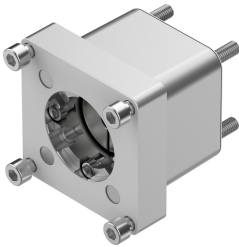

Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP65
Ambient temperature	-10 °C...60 °C
Transmittable torque	12.5 Nm
Product weight	440 g
Interface code, actuator	D40A D40B
Interface code, motor in	67A
Note on materials	RoHS-compliant