


Round cylinder DGS-40- -PPV-S2

Part number: 2872
Product to be discontinued


FESTO

With adjustable cushioning at both ends

Type to be discontinued. Available until 2016. See Support Portal for alternative products.

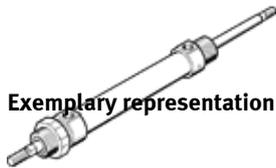

Exemplary representation

 

Data sheet

Feature	Value
Stroke	1 ... 2,000 mm
Piston diameter	40 mm
Cushioning	PPV: Pneumatic cushioning adjustable at both ends
Position detection	No
Variants	Through piston rod
Operating pressure	0.6 ... 10 bar
Mode of operation	double-acting
Ambient temperature	-20 ... 80 °C
Cushioning length	15 mm
Theoretical force at 6 bar, return stroke	633 N
Theoretical force at 6 bar, advance stroke	633 N
Pneumatic connection	G1/4