


Clip fix tool AGTC-T-SG-1+Z1

Part number: 2927784
Product to be discontinued

FESTO

In a systainer with accessories.

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

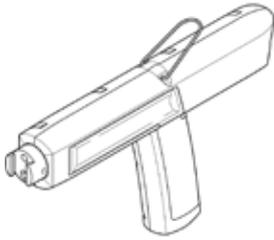

Data sheet

Feature	Value
Valve function	3/2 closed, monostable
Pneumatic connection, port 1	Female thread 1/4
Type of actuation	mechanical
Operating pressure	2 ... 6 bar
Ambient temperature	5 ... 40 °C
Material housing	PA-reinforced TPE-S
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation not possible
CE mark (see declaration of conformity)	to EU directive for machinery
Corrosion resistance classification CRC	1 - Low corrosion stress
Medium temperature	5 ... 40 °C
Max. tightening torque	15 Nm
Product weight	750 g
Material of connecting thread	Wrought aluminium alloy, anodised
Materials note	Conforms to RoHS
material retainer	Stainless spring steel
Material tool holder	High alloy steel
Tool holder	T-slot with thrust piece