


Sub-base
NAUE-1/4-NPT-1-ISO
Part number: 30427

FESTO

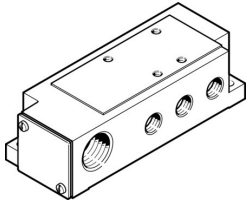

Data sheet

Feature	Value
Operating pressure	0 bar...16 bar
Approval	UL - Recognized (OL)
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-10 °C...60 °C
Degree of protection	IP65
Ambient temperature	-10 °C...60 °C
Type of mounting	With through-hole
Pilot air port 12	1/8 NPTF
Pilot air port 14	1/8 NPTF
Pneumatic connection, port 1	1/4 NPTF
Pneumatic connection, port 2	1/4 NPTF
Pneumatic connection, port 3	1/4 NPTF
Pneumatic connection, port 4	1/4 NPTF
Pneumatic connection, port 5	1/4 NPTF