


Clevis foot
LSNSG-32
Part number: 31747

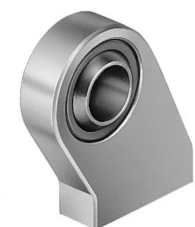

Data sheet

Feature	Value
Size	32
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 °C...150 °C
Max. load capacity	0.9 kN
Product weight	105 g
Note on materials	RoHS-compliant
Material mounting	Steel Galvanised
Material rod end bearing	Steel PTFE