


Clevis foot
LSNSG-40
Part number: 31748

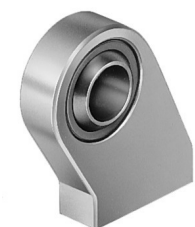

Data sheet

Feature	Value
Size	40
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 °C...150 °C
Max. load capacity	1.5 kN
Product weight	160 g
Note on materials	RoHS-compliant
Material mounting	Steel Galvanised
Material rod end bearing	Steel PTFE