


# Axial kit EAMM-A-N38-87A

Part number: 3324111

FESTO

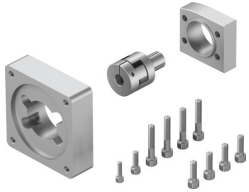

## Data sheet

Feature	Value
Nominal length	42 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	14.5 kgmm <sup>2</sup>
Transmittable torque	12.5 Nm
Product weight	430 g
Interface code, actuator	N38
Interface code, motor in	87A
Note on materials	RoHS-compliant