


Guide unit FENG-80- -GF

Part number: 34485

FESTO

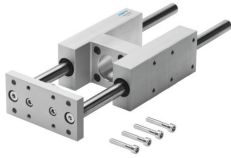

Data sheet

Feature	Value
Size	80
Stroke	10 mm...500 mm
Mounting position	optional
Guide	Plain-bearing guide
Design	Guidance
Explosion protection	The information in the certificate must be observed!
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C...80 °C
Displacement force	70 N
Additional moving mass per 10 mm stroke	76 g
Basic weight for 0 mm stroke	10720 g
Additional weight per 10 mm stroke	76 g
Centre of gravity at 0 mm stroke	54 mm
Centre of gravity additional of moving mass per 10 mm	3.9 mm
Type of mounting	Via female thread
Note on materials	RoHS-compliant
Material guide component	High-alloy steel
Material housing	Anodised wrought aluminium alloy
Material yoke plate	Tempered steel