


Guide unit FENG-63- -KF

Part number: 34490

FESTO

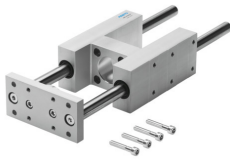

Data sheet

Feature	Value
Size	63
Stroke	10 mm...500 mm
Mounting position	optional
Guide	Recirculating ball bearing guide
Design	Guidance
Explosion protection	The information in the certificate must be observed!
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C...80 °C
Max. force Fy	1260 N
Max. force Fy static	1600 N
Max. force Fz	1260 N
Max. force Fz static	1600 N
Max. moment Mx	75 Nm
Max. torque Mx static	95 Nm
Max. moment My	90 Nm
Max. torque My static	115 Nm
Max. moment Mz	90 Nm
Max. torque Mz static	115 Nm
Displacement force	15 N
Additional moving mass per 10 mm stroke	49 g
Basic weight for 0 mm stroke	5410 g
Additional weight per 10 mm stroke	49 g
Centre of gravity at 0 mm stroke	69 mm
Centre of gravity additional of moving mass per 10 mm	4.6 mm
Type of mounting	Via female thread
Note on materials	RoHS-compliant
Material guide component	Tempered steel
Material housing	Anodised wrought aluminium alloy
Material yoke plate	Anodised wrought aluminium alloy