


Bellows suction cup VASB-15-1/8-PUR

Part number: 35418

FESTO

With sealing ring OL.

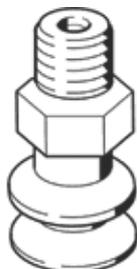

Data sheet

| Feature | Value |
|---|---|
| Nominal size | 3 mm |
| suction cup diameter | 15 mm |
| Effective suction diameter | 12 mm |
| Design structure | Vacuum connection at top round, bellows 1.5 convolutions |
| Operating medium | Atmospheric air |
| Ambient temperature | -20 ... 60 °C |
| Breakaway force at 70% vacuum | 7.9 N |
| Mounting thread | G1/8 |
| suction cup mounting | G 1/8 |
| Vacuum connection | G1/8 |
| Shore hardness | 62 |
| Materials information for screw-in stud | Zinc die-casting |
| Materials information for suction cup | TPE-U(PU) |