


Intermediate pressure regulator plate

LR-ZP-A/B-D-3

Part number: 35429

FESTO

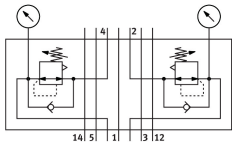

Data sheet

Feature	Value
Based on standard	ISO 5599-1
Integrated function	Pressure regulator
Design	Piston
Pressure regulation range	0.05 MPa...1.2 MPa 0.5 bar...12 bar 7.25 psi...174 psi
Inlet pressure 1	14 bar 1.4 MPa 203 psi
Approval	UL - Recognized (OL)
LABS (PWIS) conformity	VDMA24364 zone III
Product weight	1770 g
Note on materials	RoHS-compliant
Material seals	NBR
Material housing	Die-cast aluminium Steel