


Mounting plate VAME-S7-P-N-V14-A

Part number: 3581412

FESTO

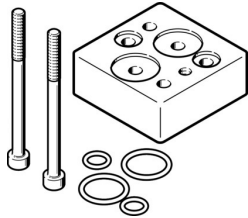

Data sheet

Feature	Value
Mounting position	optional
Operating pressure	0 MPa...1 MPa 0 bar...10 bar 0 psi...145 psi
Explosion protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air to ISO 8573-1:2010 [:-:-]
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP65
Type of mounting	With through-hole
Pneumatic connection, port 1	M5 NAMUR port pattern
Pneumatic connection, port 2	Flange 1/4 NAMUR port pattern
Pneumatic connection, port 3	G1/4
Note on materials	RoHS-compliant
Material seals	NBR
Material plate	Ematal coated aluminium