


Bellows cylinder

EB-165-65

Part number: 36487

FESTO

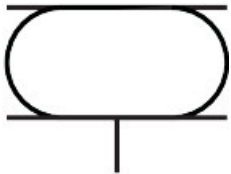

Data sheet

Feature	Value
Size	165
Required installation diameter	180 mm
Stroke	65 mm
Max. extended height	115 mm
Max. angle of inclination	20 deg
Max. offset	10 mm
Min. installation height	51 mm
Mode of operation	Single-acting
Operating pressure	0 bar...8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [:-:4]
Note on operating and pilot medium	Lubricated operation not possible
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 °C...70 °C
Reset force	200 N
Product weight	1200 g
Type of mounting	Via female thread
Pneumatic connection	G1/4
Note on materials	RoHS-compliant
Material bellows	NR/BR
Material housing	Steel Galvanised