


Axial kit
EAMM-A-T46-87A
Part number: 4048771

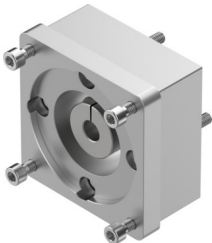

Data sheet

Feature	Value
Nominal length	44 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	5.77 kgmm ²
Transmittable torque	10 Nm
Product weight	630 g
Interface code, actuator	T46
Interface code, motor in	87A
Note on materials	RoHS-compliant