


Quick coupling plug KS2-CK-4

Part number: 4090

FESTO

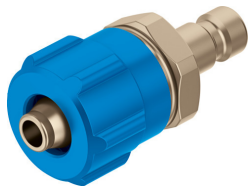

Data sheet

Feature	Value
Nominal size	2.7 mm
Operating pressure complete temperature range	-0.095 MPa...1.2 MPa -0.95 bar...12 bar -13.775 psi...174 psi
Standard nominal flow rate (standardised to DIN 1343)	86 l/min...129 l/min
Nominal flow rate standardised according to ISO 8778	93.2 l/min...139.8 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	11 g
Pneumatic connection, port 1	For tubing outside diameter of 6 mm For barbed fitting I.D. 4 mm with union nut
Material union nut	Wrought aluminium alloy, anodised
Note on materials	RoHS-compliant
Information on materials	Brass, nickel plated