


Quick coupling plug KS2-CK-3

Part number: 4091

FESTO

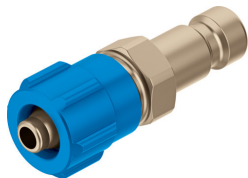

Data sheet

| Feature | Value |
|-------------------------------------------------------|----------------------------------------------------------------------------------|
| Nominal size | 2 mm |
| Operating pressure complete temperature range | -0.095 MPa...1.2 MPa -0.95 bar...12 bar -13.775 psi...174 psi |
| Standard nominal flow rate (standardised to DIN 1343) | 68 l/min...84 l/min |
| Nominal flow rate standardised according to ISO 8778 | 73.7 l/min...91.1 l/min |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C...60 °C |
| Product weight | 4 g |
| Pneumatic connection, port 1 | For tubing outer diameter of 4 mm For barbed fitting I.D. 3 mm with union nut |
| Material union nut | Wrought aluminium alloy, anodised |
| Note on materials | RoHS-compliant |
| Information on materials | Brass, nickel plated |