 



Pneumatic valve

VL-5-PK-3

Part number: 4504

FESTO

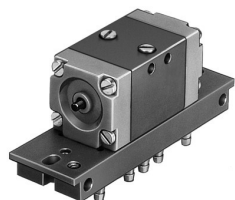

Data sheet

Feature	Value
Valve function	5/2-way, monostable
Standard nominal flow rate (standardised to DIN 1343)	105 l/min
pneumatic working port	PK-3
Operating pressure	1.5 bar...8 bar
Design	Poppet seat
Nominal size	2.5 mm
Switching time off	22 ms
Switching time on	15 ms
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	130 g
Type of mounting	On sub-base On mounting frame With through-hole Either:
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Pneumatic connection, port 3	PK-3
Pneumatic connection, port 4	PK-3
Pneumatic connection, port 5	PK-3
Note on materials	RoHS-compliant
Material sub-base	Brass PPS reinforced
Material seals	NBR
Material housing	Polymer Die-cast zinc