


# Flow control/silencer GRU-1/2

Part number: 4869

FESTO

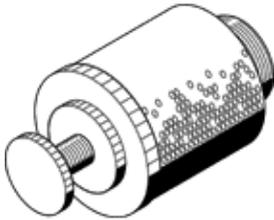

## Data sheet

Feature	Value
Valve function	Flow control – silencer function
Pneumatic connection, port 1	G1/2
Adjusting element	Knurled screw
Mounting type	Threaded
Standard nominal flow rate in flow control direction	2,500 l/min
Operating pressure	0 ... 10 bar
Ambient temperature	-10 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Medium temperature	-10 ... 60 °C
Product weight	100 g
Materials information for screw-in stud	POM
Materials note	Conforms to RoHS
Regulating screw material data	Wrought Aluminium alloy