

plastic tubing


PAN-V0-6X1-BL-20

Part number: 525466
Product to be discontinued

FESTO

Flame retardant

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

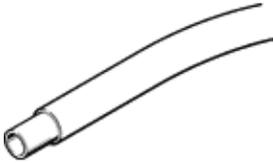

Data sheet

Feature	Value
Outside diameter	8 mm
Bending radius relevant for flow rate	30 mm
Inside diameter	4 mm
Min. bending radius	13 mm
Temperature dependent operating pressure	-0.95 ... 12 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com Mineral oil
Material fire test	UL94 V-0 (casing)
Ambient temperature	-30 ... 90 °C
Product weight according to length	0.049 kg/m
Pneumatic connection	For push-in connector outside diameter 6 mm
Colour	blue
Shore hardness	A 72 +/-4 D 57 +/-3
Materials note	Conforms to RoHS
Material tubing	Polyamide 12 PVC-P