


Manifold block VIGI-04-D-2-1/2

Part number: 525571

FESTO

For valve terminal

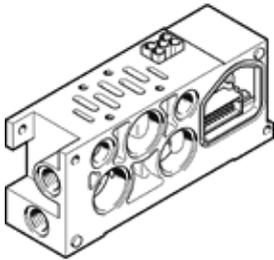

Data sheet

Feature	Value
Nominal size	10 mm
Operating pressure	-0.9 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Medium temperature	-10 ... 60 °C
Protection class	IP65
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Pilot air port 12	G1/8
Pilot air port 14	G1/8
Pneumatic ports 3/5 combined	G3/4
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G1/2
Pneumatic connection, port 4	G1/2
Pneumatic connection, port 5	G3/4
Materials information for sub-base	Aluminium die cast