


plug SEA-GS-HAR-4POL

Part number: 525928
Product to be discontinued

FESTO

[For valve terminals.](#)

[Type to be discontinued. Available until 2023. See Support Portal for alternative products.](#)

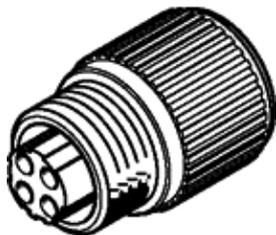

Data sheet

Feature	Value
Based on the standard	EN 61076-2-101 EN 61984
Mounting type	with thread
Assembly position	Any
Product weight	11.5 g
Electrical connection	4-pin M12x1 Straight plug / insulation displacement connection
Operating voltage range DC	≤ 32 V
Operating voltage range AC	≤ 32 V
Acceptable current load at 40°C	4 A
Surge strength	0.8 kV
Cable gland connection	Pg9
Permissible cable diameter	4 ... 5.1 mm
Permissible individual wire diameter	0.1 mm
Permissible wire diameter	1.2 ... 1.6 mm
Terminal cross-section	0.25 ... 0.5 mm ²
Protection class	IP67
Ambient temperature	-25 ... 85 °C
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material housing	Zinc die-casting Nickel plated
Permissible wire insulation	PVC