


# Suction cup without connector

## ESV-30-GT

Part number: 526000

FESTO

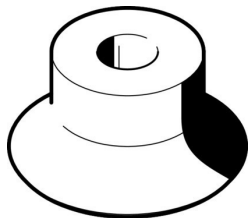

### Data sheet

Feature	Value
Height compensator for suction-cup holder	3.5 mm
Min. workpiece radius	26 mm
Suction cup diameter	30 mm
Suction cup volume	2.4 cm <sup>3</sup>
Mounting position	optional
Design	Round, bell-shaped
Suction cup shape	Round deep
Operating pressure	-0.95 bar...0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
LABS (PWIS) conformity	VDMA24364-A1-L
Ambient temperature	-10 °C...80 °C
Breakaway force at 70% vacuum	36 N
Holding force at nominal operating pressure	36 N
Lateral force at nominal operating pressure	13 N
Product weight	4.2 g
Type of mounting	Via vacuum port
Colour	Red-brown
Shore hardness	72 +/- 5
Note on materials	RoHS-compliant
Material suction cup	Vulkollan