


Suction cup without connector ESV-80-GT

Part number: 526004

FESTO

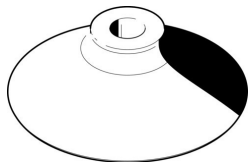

Data sheet

Feature	Value
Height compensator for suction-cup holder	7.5 mm
Min. workpiece radius	100 mm
Suction cup diameter	80 mm
Suction cup volume	28.6 cm ³
Mounting position	optional
Design	Round, bell-shaped
Suction cup shape	Round deep
Operating pressure	-0.95 bar...0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
LABS (PWIS) conformity	VDMA24364-A1-L
Ambient temperature	-10 °C...80 °C
Breakaway force at 70% vacuum	245 N
Holding force at nominal operating pressure	245 N
Lateral force at nominal operating pressure	99 N
Product weight	30.9 g
Type of mounting	Via vacuum port
Colour	Red-brown
Shore hardness	72 +/- 5
Note on materials	RoHS-compliant
Material suction cup	Vulkollan