


quick coupling plug KS3-CN-6-S

Part number: 531673
Product to be discontinued

FESTO

For self-closing quick coupling connectors, bulkhead fitting
Type to be discontinued. Available until 2019. See Support Portal for alternative products.

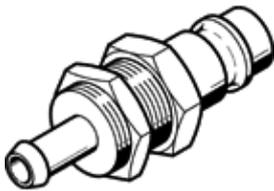

Data sheet

Feature	Value
Nominal size	4.9 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	378 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	32 g
Pneumatic connection, port 1	CN-6
Materials note	Conforms to RoHS