


Quick coupling plug KS4-CK-9

Part number: 531683

FESTO

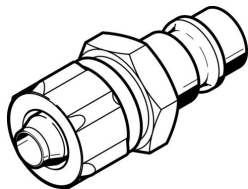

Data sheet

Feature	Value
Nominal size	7.4 mm
Operating pressure complete temperature range	-0.095 MPa...1.2 MPa -0.95 bar...12 bar -13.775 psi...174 psi
Standard nominal flow rate (standardised to DIN 1343)	725 l/min...1197 l/min
Nominal flow rate standardised according to ISO 8778	785.9 l/min...1297.5 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	26 g
Pneumatic connection, port 1	For barbed fitting inside diameter of 9 mm with union nut
Material union nut	Wrought aluminium alloy, anodised
Note on materials	RoHS-compliant
Information on materials	Brass, nickel plated