


# quick coupling plug KS4-CK-9-S

Part number: 531686  
Product to be discontinued

FESTO

For self-closing quick coupling connectors, bulkhead fitting  
Type to be discontinued. Available until 2019. See Support Portal for alternative products.

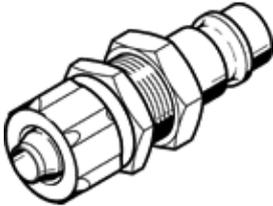

## Data sheet

Feature	Value
Nominal size	7.4 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	1,017 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	69 g
Pneumatic connection, port 1	CK-9
Materials note	Conforms to RoHS