 



Branching module MS4N-FRM-1/4-Y-Z

Part number: 531955

FESTO

Includes pressure switch without indicator, direction of flow: from right to left.

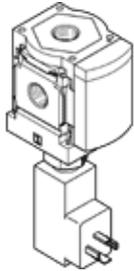

Data sheet

| Feature | Value |
|--|--------------------|
| Assembly position | Any |
| Design structure | Branching module |
| Operating pressure | 0 ... 12 bar |
| Standard nominal flow rate in main flow direction 1->2 | 4,600 l/min |
| Standard nominal flow rate outlet at top | 1,500 l/min |
| Standard nominal flow rate outlet at bottom | 1,500 l/min |
| Operating medium | Compressed air |
| Corrosion resistance classification CRC | 2 |
| Storage temperature | -10 ... 60 °C |
| Medium temperature | -10 ... 60 °C |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 405 g |
| Pneumatic connection, port 1 | NPT1/4-18 |
| Pneumatic connection, port 2 | NPT1/4-18 |
| Pneumatic connection, port 3 | NPT1/4-18 |
| Pneumatic connection, port 4 | NPT1/4-18 |
| Materials information, housing | Aluminium die cast |