


Limit switch attachments

DAPZ-SB-I-30DC-DSAM-RO

Part number: 534473

FESTO

For semi-rotary drives with assembly interface per VDI/VDE 3845
 Suitable for all DAPS quarter turn actuators, but only for DRD/DRE in
 sizes 4 through 225. For DRD/DRE Quarter turn actuators in sizes 1
 through 2, can only be mounted to sizes 375 through 880 with DAPZ-
 SBZ-... adapter.

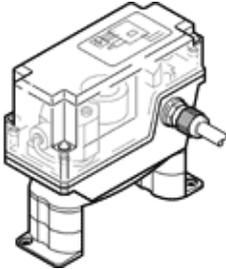

Data sheet

Feature	Value
Based on the standard	EN 60947-5-6 VDI/VDE 3845 (NAMUR)
Design	Angular
Assembly position	Any
Short circuit strength	Yes
Fieldbus interface	AS interface: flat cable plug
Switching element function	Normally closed contact
Polarity protected	for all electrical connections
Measuring principle	Inductive
Switching position indicator	No
Insulation voltage	50 V
Nominal operating voltage DC	30 V
Surge strength	0.8 kV
Degree of contamination	3
Corrosion resistance classification CRC	2
Protection class	IP65
Ambient temperature	-25 ... 85 °C
Note regarding fieldbus interface	AS-Interface
Materials note	Conforms to RoHS
Materials information for seals	EPDM
Notes on materials for housing cover	PC
Notes on materials for housing socket	PA
Notes on materials for console	PA