


Branching module MS12-FRM

Part number: 535035

FESTO

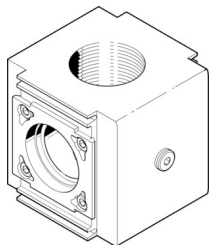

Data sheet

Feature	Value
Mounting position	optional
Design	Branching module
Operating pressure	0 bar...20 bar
Standard nominal flow rate in main flow direction 1->2	25000 l/min...42000 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [-:--]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C...60 °C
Media temperature	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Pneumatic connection, port 4	G1
Material housing	Die-cast aluminium