


Basic block CDVI5.0-GB8-DN

Part number: 535839

FESTO

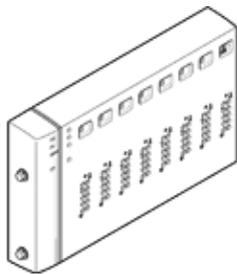

Data sheet

Feature	Value
Length	244 mm
Max. number of valve positions	8
Corrosion resistance classification CRC	3
Authorisation	C-Tick
Product weight	2,360 g
Mounting type	With internal thread and stud bolt
Scavenging orifice connection	G1/8
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 4	G1/8
Materials note	Conforms to RoHS