


sub-base VABS-B6-PB-Q

Part number: 537519

FESTO

For external, auxiliary pilot air.

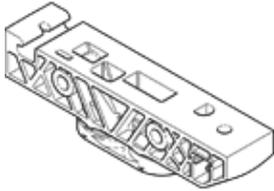

Data sheet

| Feature | Value |
|---|---|
| Grid dimension | 21 mm |
| Corrosion resistance classification CRC | 2 |
| Max. tightening torque, valve mounting | 2 Nm |
| Max. tightening torque, wall mounting | 3 Nm |
| Product weight | 22 g |
| Pilot air port 12 | M5 |
| Pilot air port 14 | M5 |
| Pneumatic connection, port 1 | For 18 mm cartridge |
| Pneumatic connection, port 3 | G1/4 |
| Materials note | Free of copper and PTFE Conforms to RoHS |
| Materials information for sub-base | PA-reinforced |