


Manifold block CPASC1-PRS-2-5-M5-MP

Part number: 539898
Product to be discontinued

For valve terminal CPA-SC.

Type to be discontinued. Available until 2014. See Support Portal for alternative products.

FESTO

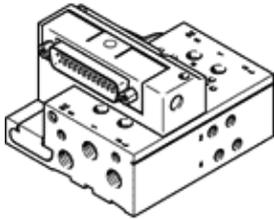

Data sheet

Feature	Value
Grid dimension	10.5 mm
Pressure zone separation	1 and 3 and 5
Assembly position	Any
Max. number of valve positions	2
Valve position identification	Label
Operating pressure	10 bar
Corrosion resistance classification CRC	2
Medium temperature	-5 ... 50 °C
Sound pressure level	85 dB(A)
Protection class	IP40
Ambient temperature	-5 ... 50 °C
Authorisation	c UL us - Recognized (OL)
Product weight	430 g
Valve interface, electrical	3-pin
Mounting method for sub-base	with through hole with top-hat rail
Mounting type	Optional with through hole with top-hat rail
Auxiliary pilot air port 12/14	M5
Scavenging orifice connection	M5
Pilot exhaust port 82	M5
Pilot exhaust port 82/84	M5
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	M5
Pneumatic connection, port 3	G1/8
Pneumatic connection, port 4	M5
Pneumatic connection, port 5	G1/8
Materials information for sub-base	Wrought Aluminium alloy Anodised