


Ball valve actuator unit VZPR-BPD-22-R114

Part number: 540515

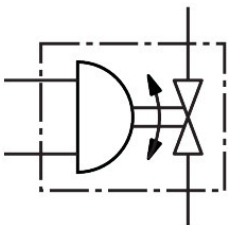

Data sheet

Feature	Value
Design	2-way ball valve Semi-rotary drive
Type of actuation	Electric Pneumatic
Mounting position	optional
Type of mounting	CNOMO Via female thread
Connection Process valve	Rp1 1/4
Switching position indicator	Knob actuator direction = flow direction
Nominal size DN	32
Operating pressure of ball valve drive unit	1 bar...8.4 bar
Nominal pressure PN	40
Media temperature	-20 °C...150 °C
Ambient temperature	-20 °C...80 °C
LABS (PWIS) conformity	VDMA24364 zone III
Product weight	3200 g
Corrosion resistance class CRC	1 - Low corrosion stress