


Power supply unit SVG-3/400VAC-48VDC-20A

Part number: 542405
Product to be discontinued

FESTO

With 48 V DC rated output voltage and 20 A rated output current.
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

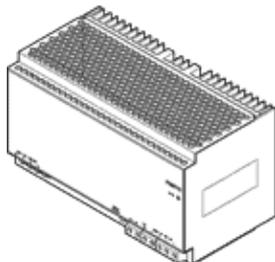

Data sheet

Feature	Value
Width	125 mm
Height	130 mm
Length	240 mm
Assembly position	Free convection
Primary supply	Three-phase
Input current	2,3 - 1,9 A
Nominal output voltage DC	48 V
Nominal output current	20 A
Input voltage range AC	400 ... 500 V
Power failure buffering	50 ms
Line frequency	45 ... 65 Hz
CE mark (see declaration of conformity)	to EU directive for EMC to EU directive low-voltage devices
Storage temperature	-40 ... 85 °C
Relative air humidity	95%
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Authorisation	C-Tick c UL us - Listed (OL)
Product weight	3,500 g
Mounting type	with top-hat rail
Materials note	Contains PWIS substances