


Sub-base
VMPA2-AP-2-1-EMM-2
Part number: 546807

FESTO

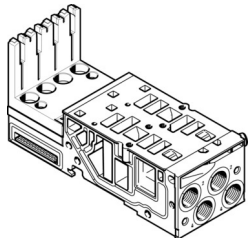

Data sheet

Feature	Value
Width	42 mm
Length	107.3 mm
Grid dimension	21 mm
Max. number of valve positions	2
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure	0.3 MPa...0.8 MPa 3 bar...8 bar
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	210 g
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 4	G1/8
Note on materials	RoHS-compliant
Material sub-base	Die-cast aluminium