


# Power supply unit SVG-1/230VAC-24VDC-5A

Part number: 547867  
Product to be discontinued

FESTO

With 24 V DC rated output voltage and 5 A rated output current.  
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

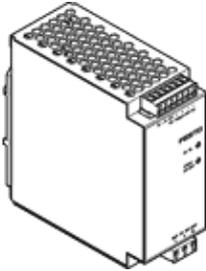

## Data sheet

Feature	Value
Width	55 mm
Height	130 mm
Length	125 mm
Assembly position	Free convection
Primary supply	Single-phase
Input current	1,9 - 0,8 A
Nominal output voltage DC	24 V
Nominal output current	5 A
Input voltage range AC	100 ... 240 V
Power failure buffering	20 ms
Line frequency	45 ... 65 Hz
CE mark (see declaration of conformity)	to EU directive for EMC to EU directive low-voltage devices
Storage temperature	-40 ... 85 °C
Relative air humidity	95%
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Authorisation	C-Tick c UL us - Listed (OL)
Product weight	830 g
Mounting type	with top-hat rail
Materials note	Contains PWIS substances