


Cover cap CPX-M-AK-C

Part number: 548753

FESTO

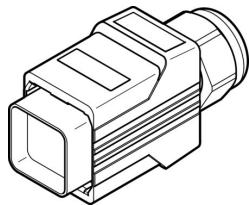

Data sheet

Feature	Value
Width	30 mm
Height	58 mm
Length	22 mm
Approval	UL94 V0
Product weight	54 g
Degree of protection	IP65 IP67 In assembled state To IEC 60529
Ambient temperature	-5 °C...50 °C
Storage temperature	-40 °C...70 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	1 - Low corrosion stress
Material housing	Die-cast zinc Nickel-plated
Material seals	NBR
Relative air humidity	5 - 90% Non-condensing