


Fibre-optic cable
SOOC-TB-M4-1-R25
Part number: 552814

FESTO

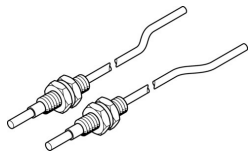

Data sheet

Feature	Value
Note on materials	RoHS-compliant
Measurement method	Through-beam sensor
Min. object diameter	0.35 mm
Fibre-optic - special feature	Standard
Operating distance	400 mm
Ambient temperature	-55 °C...70 °C
Head size	M4
Fibre-optic length	1 m
Min. bending radius	25 mm
Max. tightening torque	2 Nm
Outside diameter	2.2 mm
Material housing	Copper alloy PVC Nickel-plated
Material fibre-optic	PE
Degree of protection	IP66
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III