


# Fibre-optic cable SOOC-TB-H-M4-1-R40

Part number: 552817  
Product to be discontinued

FESTO

[Suitable for SOE4 fibre-optic units.](#)

[Type to be discontinued. Available until 2022. See Support Portal for alternative products.](#)

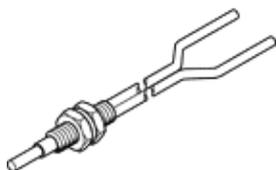

## Data sheet

Feature	Value
Materials note	Conforms to RoHS
Measurement method	Through-beam sensor
Minimal object diameter	0.2 mm
Fibre-optic cable - special feature	Large working range
Working range	650 mm
Ambient temperature	-55 ... 70 °C
Size, head	M4
Fibre optic cable length	1 m
Min. bending radius	40 mm
Max. tightening torque	2 Nm
Outside diameter	2.2 mm
Material housing	High alloy steel, non-corrosive
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364 zone III