


Fibre-optic cable SOOC-TB-M-A5-2-R25

Part number: 552827
Product to be discontinued

FESTO

[Suitable for SOE4 fibre-optic units.](#)

[Type to be discontinued. Available until 2022. See Support Portal for alternative products.](#)

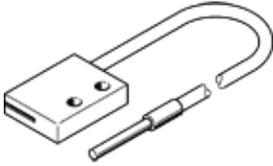

Data sheet

Feature	Value
Materials note	Conforms to RoHS
Measurement method	Through-beam sensor
Minimal object diameter	0.1 mm
Fibre-optic cable - special feature	Series
Working range	250 mm
Ambient temperature	-55 ... 70 °C
Size, head	Rectangle 10x10x5 mm
Fibre optic cable length	2 m
Min. bending radius	25 mm
Outside diameter	2.2 mm
Material housing	Nickel-plated brass
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364 zone III