
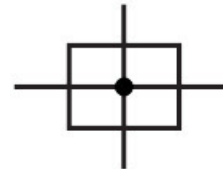


Distributor block MS4N-FRM-FRZ

Part number: 554101

FESTO

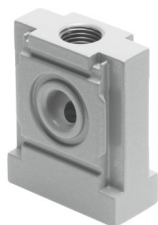

Data sheet

Feature	Value
Mounting position	optional
Design	Branching module
Operating pressure	0 bar...14 bar
Standard nominal flow rate in main flow direction 1->2	4050 l/min
Standard nominal flow rate, outlet upwards	3250 l/min
Standard nominal flow rate, outlet downwards	2900 l/min
Approval	c UL us - Recognized (OL)
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-10 °C...60 °C
Media temperature	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Product weight	60 g
Pneumatic connection, port 3	1/4 NPT
Pneumatic connection, port 4	1/4 NPT
Note on materials	RoHS-compliant
Material housing	Die-cast aluminium