


Solenoid coil VACC-S13-18-A1-1U

Part number: 562890

FESTO

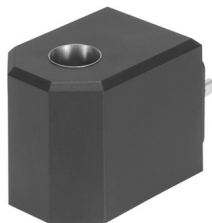

Data sheet

Feature	Value
Type of actuation	Electric
Mounting position	optional
Switching position indicator	no
Duty cycle	100%
Insulation material class	H
Characteristic coil data	24 V DC: 2.1 W 24 V AC: 50/60 Hz, Power 2.1 VA
Permissible voltage fluctuations	-15%/+10%
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP65
Ambient temperature	-20 °C...60 °C
Product weight	210 g
Electrical connection	Type A Plugs To EN 175301-803
Note on materials	RoHS-compliant
Material solenoid coil	PA UP