


# Push-in sleeve QSH-F-8-6

Part number: 564893

FESTO

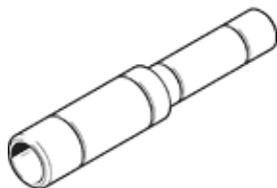

## Data sheet

Feature	Value
Size	Standard
Nominal size	4 mm
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	3
Food safety	to manufacturer's declaration
Ambient temperature	0 ... 150 °C
Authorisation	Germanischer Lloyd
Product weight	7.2 g
Pneumatic connection, port 1	Push-in sleeve QS-8
Pneumatic connection, port 2	Push-in sleeve QS-6
Materials note	Conforms to RoHS
Materials information, housing	Brass Chromium and nickel plated