


Manifold rail

VABM-L1-10AS-M5-2

Part number: 566522

FESTO

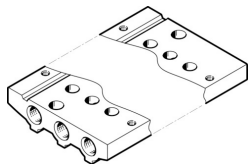

Data sheet

Feature	Value
Grid dimension	10.5 mm
Max. number of valve positions	16
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Approval	RCM trademark c UL us - Recognized (OL)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque H-rail mounting	1.5 Nm
Max. tightening torque for valve mounting	0.45 Nm
Max. tightening torque wall mounting	3 Nm
Product weight	26 g
Pneumatic connection, port 1	M5
Pneumatic connection, port 3	M5
Pneumatic connection, port 5	M5
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy