 



End plate VMPAL-EPL-SD9-IP40

Part number: 570777

FESTO

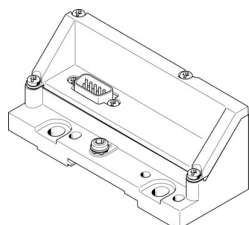

Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Max. number of valve positions	8
Valve terminal structure	Valve sizes can be mixed
Max. number of valve coils	8
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure	0.3 MPa...0.8 MPa 3 bar...8 bar
Nominal operating voltage DC	24 V
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP40
Note on degree of protection	In assembled state
Ambient temperature	-5 °C...50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin plug
Electrical connection 1, connection type	Plugs
Electrical connection 1, connector system	Sub-D
Electrical connection 1, number of connections/cores	9
Note on materials	RoHS-compliant
Material end plate	Die-cast aluminium PA-reinforced