


Plug FBS-SCRJ-PP-GS

Part number: 571017

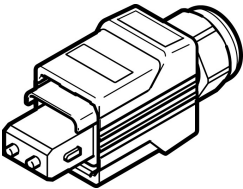

Data sheet

Feature	Value
Product weight	60 g
Note on fieldbus interface	PROFINET FOC
Specification Ethernet cable	Fibre-optic cable Polymer fibre 980/1000 µm Individual wire diameter: 2.2 mm
Permissible cable diameter	6.5 mm...9.5 mm
Degree of protection	IP65 IP67 To IEC 60529
Ambient temperature	-40 °C...70 °C
Storage temperature	-40 °C...70 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	1 - Low corrosion stress
Material housing	Die-cast zinc Nickel-plated
Material seals	NBR TPE