


Fixed flow restrictor-SET VMPA1-FT-NW0.3-1.7

Part number: 572543

FESTO

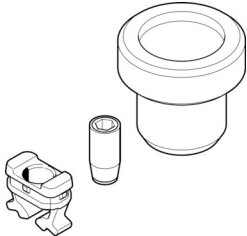

Data sheet

Feature	Value
Valve function	Flow control function
Pneumatic connection, port 1	Sub-base
Standard nominal flow rate in flow control direction	3.5 l/min...115 l/min
Operating pressure	-0.9 bar...10 bar
Ambient temperature	-5 °C...60 °C
Nominal size	0.3 mm...1.7 mm
Mounting position	optional
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...40 °C
Media temperature	-5 °C...60 °C
Note on materials	RoHS-compliant
Material retaining bracket	POM
Material hollow bolt	Wrought aluminium alloy