


Plug
NECU-S1W9-C2-APB
Part number: 574589

FESTO

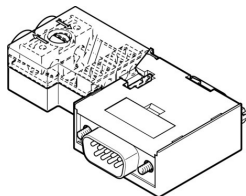

Data sheet

Feature	Value
Type of mounting	4-40 UNC-2B
Product weight	57.48 g
Field bus interface	Sub-D, 9-pin, socket
Electrical connection 1	Sub-D plug, 9-pin
Electrical connection 2	IDC terminal
Baud rate	12 Mbit/s
Permissible cable diameter	8 mm 8 mm
Connection cross section	0.08 mm ² ...0.5 mm ²
Degree of protection	IP20
Ambient temperature	-20 °C...70 °C
Relative air humidity	75% at 25°C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	1 - Low corrosion stress
Material housing	PC-reinforced