


# Vertical pressure supply plate VABF-L1-P3A3-M7

Part number: 574592

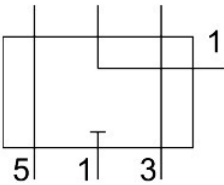

## Data sheet

| Feature                                   | Value                                      |
|-------------------------------------------|--------------------------------------------|
| Grid dimension                            | 10.5 mm                                    |
| Max. number of valve positions            | 1                                          |
| Operating pressure                        | -0.09 MPa...1 MPa<br>-0.9 bar...10 bar     |
| Approval                                  | RCM trademark<br>c UL us - Recognized (OL) |
| Corrosion resistance class CRC            | 2 - Moderate corrosion stress              |
| LABS (PWIS) conformity                    | VDMA24364-B1/B2-L                          |
| Max. tightening torque for valve mounting | 0.45 Nm                                    |
| Product weight                            | 220 g                                      |
| Pneumatic connection, port 1              | M7                                         |
| Note on materials                         | RoHS-compliant                             |
| Material plate                            | Wrought aluminium alloy                    |